

# Managed Rack PDU MPH2™ / Basic Rack PDU MPE™



## Mounting Options in Knürr DCM® Rack


The PDUs can be installed in Knürr DCM® rack in different ways using various mounting brackets:

- ① MPH2 SpeedMount InstKit DCM H2000 – order no. 03.951.405.0.001 (kit includes: 1 bottom bracket, 1 upper bracket)
- ② Mounting Kit Z-Shape – order no. 03.951.406.0.001 (kit includes: 2 brackets, 2 spring nuts, 2 screws)
- ③ Mounting Kit Standard – supplied with the PDU (kit includes: 2 brackets, ② spring nuts + screws, 2 mounting buttons + ② screws)
- ④ PDU Mounting Kit Short – order no. 01.147.813.9 (kit includes: 2 brackets, 4 spring nuts + washers + screws, 4 cage nuts + screws)
- ⑤ PDU Mounting Kit Long – order no. 01.147.814.9 (kit includes: 2 brackets, 4 spring nuts + washers + screws, 8 cage nuts + screws)



Based on the PDU length and rack height, you can choose the mounting method which best suits your needs.

MPH2/MPE Length [mm]	Rack Height 2000 mm			
	Fixed Installation		Toolless Installation	
916.5	③a + ④ 	③a + ⑤ 	③b + ④ 	③b + ⑤ 
1004	same as above (length 916.5 mm)		same as above (length 916.5 mm)	
1736.5	② 	③a 	① 	

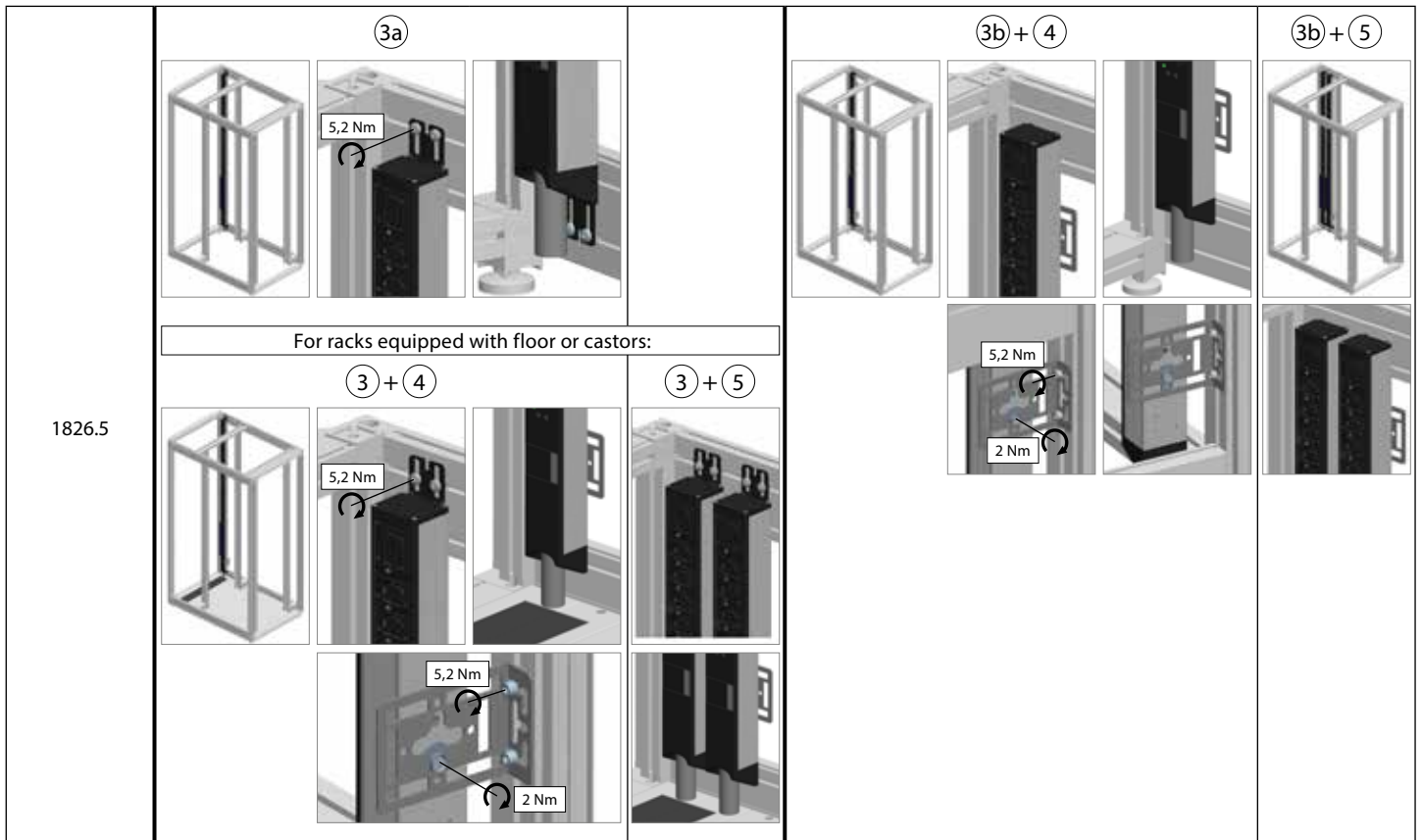

MPH2/MPE Length [mm]	Rack Height 2200 mm	
	Fixed Installation	Toolless Installation
916.5	3a + 4 or 5 (same as at rack H2000)	3b + 4 or 5 (same as at rack H2000)
1004	3a + 4 or 5 (same as at rack H2000 / PDU L916.5)	3b + 4 or 5 (same as at rack H2000 / PDU L916.5)
1736.5	3a + 4 or 5 (same as at rack H2000 / PDU L916.5)	3b + 4 or 5 (same as at rack H2000 / PDU L916.5)
1826.5	3a + 4 or 5 (same as at rack H2000 / PDU L916.5)	3b + 4 or 5 (same as at rack H2000 / PDU L916.5)