

Vertiv™ CSV1000 Series Rack Mount KVM Switches



Features & Benefits

Multi-user, small form factor Vertiv™ CSV1000 KVM switches are designed specifically for IT Rooms, small Data Centers and Branch Offices

Different bundle options are available which means KVM cables ship with the unit, simplifying the order and installation process.

Consolidated Server Management

- Simplified local access and control of your server resources all from a single console.
- Ability to connect and control 8 / 16 computers directly and control up to 256 computers with cascading

Easy to manage

- Switch between targets with the simple on-screen display (OSD), hot-key operation and scan mode
- Flexibility to mount KVM switches in same U-space on various LCD console*
- Installation is simple and fast, only need to connect cables to the correct ports, no software installation required

Authentication

- Only authorized users can view and control computers; up to eight users and an administrator

"Flexible" compact entry level KVM switches for SMB server rooms.


To help customer with access and control of server resources and improve work efficiency, Vertiv has launched a new generation of Vertiv™ CSV1000 series rack KVM switches.

Vertiv™ CSV1000 switches offer a cost-efficient solution to streamline access and control to server resources and increase speed to remediation and operational efficiencies.

These multi-user KVM switches, available in 8 and 16 port models, provide a straightforward user experience and help conserve space in your server room and reduce cable clutter.



Vertiv CSV 1008

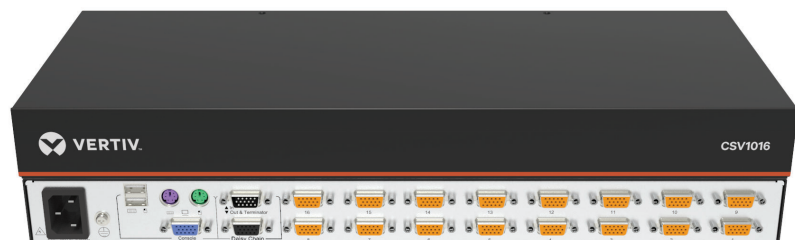

Vertiv CSV 1016

Part Number	Model	Description
02830928	CSV1008	1 local user, 8 ports analog KVM - comes with 8 x VGA/USB cable and Jumper cord: Plug C14 to connector C13
02830929	CSV1016	1 local user, 16 ports analog KVM - comes with 16 x VGA/USB cable and Jumper cord: Plug C14 to connector C13
02831075	CV-1002	Cascade Cable
02840090	CFPCAB3-USB	CFP LCD and CSV1000 3 Meter Cable
02840091	CFPCAB5-USB	CFP LCD and CSV1000 5 Meter Cable
F2159857		CSV1008 / CSV1016 - Mounting Bracket for Dell KMM185 LCD

Technical Specifications

	CSV1008	CSV1016
Form Factor	1U	
Dimension	Height: 44 mm Width: 432 mm Depth: 172 mm	
Weight	2.4 kg	2.5 KG
Device Connectors	8 DB15 KVM Ports 2 USB Ports 2 PS/2 Ports 1 Local Display VGA Port 2 DB15 Cascade Ports	16 DB15 KVM Port 2 USB Ports 2 PS/2 Ports 1 Local Display VGA Port 2 DB15 Cascade Ports
Cascade Device Quantity	248 Maximum	256 Maximum
Bundled Cables	8 units of 2M VGA/USB Cables	16 units of 2M VGA/USB Cables
Local Access	1 Local User	
Feature Include	KVM access OSD Keystroke Switching Multi-Users: 1 Admin + 8 Users Cascade support up to 16 Units	
Video Support	Appliance - VGA Targets - VGA	
Support Resolution	1920*1200@60Hz	
Autoscan Interval	3/8/15/30 seconds	
Support LCD Console Rear Mount (Same RU)	Vertiv CLRA 18.5 LCD Console Dell LRA185KMM	
Power Supply Specification	100-240V 50-60Hz AC 12v, 10W max Internal Single IEC C14 inlet connector Jumper Cord C13 to C14 Included	
Environmental	Operating Temperature: 0~40°C Storage Temperature: -20~60°C Operating Humidity: 20% to 85% Storage Humidity: 10% to 90%	
Approved Agencies	CE, RoHS	
Warranty	2 Years Standard Warranty	